

STAIR TREADS & FLOOR TILES - Vinyl or Rubber

Industrial duty stair treads provide traction and protect stairs from heavy traffic. Meets Federal Spec. RR-T-650E and GSA-FSS standard ZZ-T-001237. **Vinyl Ribbed Tread** measures 12"D x 1 1/4" nose x 3/16" thick and are only available in Brown, Black, Beige and Light Gray. **Rubber** models measure 12 1/2"D x 1 1/2" nose x 1/4" thick and are not available in Brown. For rubber treading choose between **Round Disc pattern** for easy cleaning or **Diamond pattern** for heavy traffic with adjustable nose angle of 60-90° for easy installation on pan filled molded concrete or terrazzo stairs. **7"H Riser Covers** provide complete protection for stair fronts. Matching **Rubber Tiles** are ideal for landings, entryways and more. Disc texture is 1/8" thick. Diamond texture is 7/32" thick. Use neoprene contact adhesive and epoxy nose caulk for safe, lasting installation (sold separately). **Add color suffix: Brown (BN), Beige (BG), Gray (LG), Charcoal (CH), Walnut (WL), Slate (GY) or Black (BK).**



AS LOW AS
\$15.75
per tread

W"	Pkg. Qty.	VINYL TREADS RIB PATTERN		VINYL RISER COVER		RUBBER TREADS DIAMOND PATTERN			RUBBER TREADS ROUND DISC PATTERN			RUBBER RISER COVER	
		Model	Price Each	Model	Price Each	Model	Price Each	Model	Price Each	Model	Price Each	Model	Price Each
36	4	FD239570	\$15.75	FD239761	\$7.25	3	FD238103	\$32.95	FD238109	\$29.95	FD238115	\$15.75	
42	4	FD239571	18.25	FD239762	8.50	3	FD238104	37.95	FD238110	34.95	FD238116	18.25	
48	4	FD239572	21.00	FD239763	9.75	3	FD238105	42.95	FD238111	39.95	FD238117	21.00	
54	---	---	---	---	---	3	FD238106	48.95	FD238112	44.95	FD238118	23.50	
60	4	FD239573	26.25	FD239764	12.25	3	FD238107	53.95	FD238113	49.95	FD238119	26.25	
72	4	FD239574	31.50	FD239765	14.50	3	FD238108	64.95	FD238114	59.95	FD238120	31.50	

Choose Vinyl or Rubber to Meet Your Needs

RUBBER TILE - 24"W x 24"L		Model	Qty.	Price Each	Contact Adhesive	Price
Model	FD238227	FD238227	1	\$18.00	per quart, covers 19 sq. ft.	
Model	FD238228	FD238228	1	\$26.00	per quart, covers 75 linear. ft.	
Model	FD239406	FD239406	1	\$52.00	per gallon, covers 75 linear. ft.	

OUTDOOR RECYCLED RUBBER STAIR TREADS

Provides a slip resistant surface for exterior stairways & steps. Made from 100% recycled tires. 5/16" thick stair treads offer 12 3/8" tread depth with 1 1/2" inside nose depth. Diamond pattern extends back 9 3/8" from nose to provide a slip resistant surface. Back 3" of tread is smooth with a square nose pattern so tread can be cut to fit tread depth. Black only. Installs easily using an Epoxy Adhesive (sold separately). 1 Gallon Adhesive covers up to 150 linear feet of treads.



W"	Model	Price
36	FD443384	\$46.95
42	FD443385	54.95
48	FD443386	61.95
54	FD443387	69.95
60	FD443388	77.95
72	FD443389	92.95


Model FD443390 Epoxy Adhesive \$82.95/per Gal.

POLYVINYL FLOOR COVERING

Designed for industrial and commercial use. 0.075" thick (0.055" on clear covering) padding provides attractive pattern design and improves traction. Hides cracks and stains. Solid polyvinyl matting provides a moisture/vapor barrier for hard floors. Non-porous surface allows easy clean-up with soap and water. Easy installation; no need for adhesives. Easy to cut for custom fit. **Diamond and Levant** available in Slate Gray and Midnight Black only. **Specify Color Suffix for color covering: Slate Gray (GY), Midnight Black (BK), Racing Blue (BL), Forest Green (GN), Brick Red (RD) and Sandstone (SD).**

W' x L'	Covers Sq.	Pattern				Price
		Coin	Rib	Diamond	Levant	
COLOR COVERING						
7 1/2 x 17	127 1/2	FD239699	FD239702	FD239705	---	\$279.95
8 x 22	176	FD239700	FD239703	---	---	389.95
9 x 20	180	---	---	FD239706	---	389.95
10 x 24	240	FD239701	FD239704	FD239707	---	527.95
9 x 60	540	---	---	FD239708	---	1034.95
CLEAR COVERING						
7 1/2 x 17	127 1/2	---	FD269089	---	---	234.95
7 1/2 x 20	150	---	FD269090	---	---	275.95
9 x 20	180	---	FD269091	---	---	329.95
10 x 22	220	---	---	FD269092	---	405.95

AS LOW AS
\$1.84
sq. feet

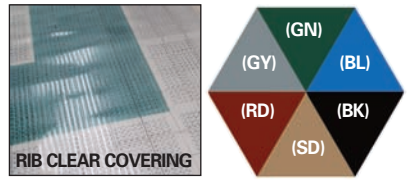

CARPET PROTECTION FILM

Protect carpets during commercial and residential construction, remodeling or moving. Highly durable, 2.5 Mil thick puncture resistant polyethylene film is made to last for days on all grades of carpet, flexibly enduring traffic without punctures or tears. Adhesive backing keeps film in place and allows easy application and removal without residue. Optional **Push Dispenser** saves bending, applies film efficiently.



48 HOUR SHIPMENT


Model	W" x L'	Price Per Roll
FD238069	24 x 200	\$48.95
FD238070	36 x 200	72.95
FD261288	24 x 500	104.95
FD261290	36 x 500	148.95

PUSH DISPENSER
FD238100 109.00



TILE MATTING

Tile matting is great for garages, shops and work areas. Won't chip or crack and helps reduce dirt tracked into homes. **Round Disc Tiles** are interlocking PVC tiles that resist chemicals. Jigsaw edges tightly lock without adhesive. 5/16" thick. Raised grid underside pattern for slip resistance. **Diamond & Levant** (concrete appearance) Tiles are made of solid virgin polyvinyl with gloss finish. Easy peel and stick installation with pressure sensitive adhesive backing. Backing seals floors out from moisture and prevents concrete damage. Base is 0.095" (95 mil) thick.

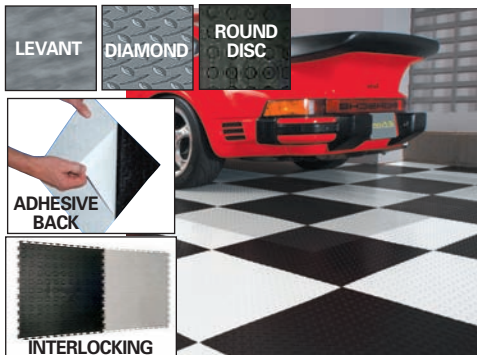

AS LOW AS
\$2.80
each

W" x L"	Ctn. Qty.	Color	Diamond	Levant	Round Disc	Price/Ctn.
12 x 12	20	BK, GY, WH	FD269093	FD269095	---	\$56.00
24 x 24	10	BK, GY, WH	FD269094	FD269096	---	112.00
19 1/2 x 19 1/2	12	BK, GY	---	---	FD239631	216.00