

VERTICAL BAR RACK



FD246300

**SAME DAY
IN STOCK
SHIPMENT**

**6000 lb.
capacity**

AS LOW AS
\$129

**EASY
ASSEMBLY**

ALL-WELDED



FD652262

Efficiently holds long pipe stock and lumber. **Rack A.** Long pieces stack vertically; shorter pieces are stored on the 3 pan shelves spaced at 21" intervals. Bottom pan is 6"D with 1 1/2"H flange. *Ships Ready to Assemble or All-Welded. **Rack B** has four 10"W bays, each with 1,500 lb. capacity and safety chain. All welded steel with powder coat finish.

Rack Style	W" x D" x H"	Capacity	Model	Price Each	
				1-3	4+
A Unassembled	36 x 24 x 72	2000	FD246999	\$137.95	\$129.00
A Unassembled	39 1/2 x 24 x 84	3000	FD246300	199.95	189.95
A All Welded	36 x 24 x 84	3000	FD258298	239.95	225.95
B All Welded	48 x 24 x 60	6000	FD652262	415.95	394.95

VERTICAL SHEET RACK

**Choice of
Floor or
Mobile**



**SAME DAY
IN STOCK
SHIPMENT**

Stores sheet materials. Includes 3 pairs of 1.3-1/16" dia. steel pipe uprights at 12", 26" and 36" heights steel framed wooden deck with lacquer finish. 1 1/2"H x 1/2" thick angle iron frame has rounded safety edges. Provisions included for floor anchoring. Blue enamel finish. **Frame sockets permit 3 1/2" upright adjustments** (24"W has 7 sockets; 30"W has 9 sockets). **Mobile Rack** has 6" mold-on rubber wheels and 2,000 lb. capacity

FLOOR RACK			MOBILE RACK		
Model	Price	L" x W"	Model	Price	
FD652208	\$314.95	48 x 24	FD652214	\$379.95	
FD652213	399.95	60 x 30	FD652215	464.95	

CORROSION RESISTANT CANTILEVER SHELVING & RACK




**WIRE
SHELVES**

**Customize to
Your Bulk
Storage Needs!**

**SAME DAY
IN STOCK
SHIPMENT**

NSF®

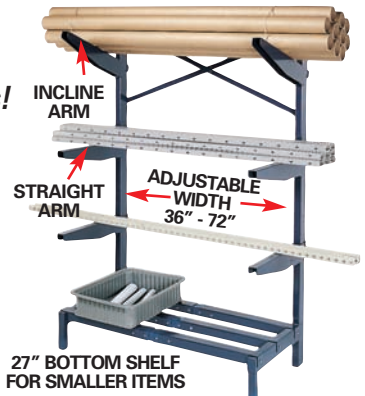

**INCLINE
ARM**

**STRAIGHT
ARM**

**ADJUSTABLE
WIDTH
36" - 72"**


**27" BOTTOM SHELF
FOR SMALLER ITEMS**

Offers 800 lb. capacity per pair of arms. Global's **Nexelon** finish protects against bacteria, mold, cold weather and chemicals. 10 Year Limited Warranty against rust and corrosion. 12 gauge steel frame adjusts to 36", 48", 60" or 72"W. Frame measures 72"H x 27"D and includes 27"D x 8-1/2"H bottom shelf. Allows arm adjustments at 6" increments. **Cantilever Shelving** includes frame, 3 pairs of straight arms and 3 wire shelves. **Wire Shelves** easily rest on straight arms. Configure your own **Cantilever Rack** using 1 **Frame** and 24"L **Straight Arms** to store square or flat items or 20° **Inclined Arms** to store pipes and round stock.

CANTILEVER SHELVING			ADDITIONAL WIRE SHELVES		CANTILEVER RACK		
W" x D"	Model	Price	Model	Price	Model	Description	Price
36 x 24	FD245644	\$419.95	FD188556F	\$46.95	FD235947	Frame	\$252.95/each
48 x 24	FD245645	438.95	FD188558F	58.95	FD235948	Straight Arms	33.95/pair
60 x 24	FD245646	462.95	FD188560F	71.95	FD235949	20° Incline Arms	27.95/pair
72 x 24	FD245647	494.95	FD188564F	92.95			

BAR STOCK STORAGE RACK

12000 lb. capacity

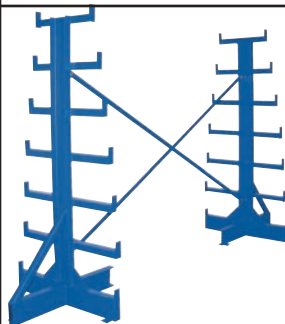

Increase storage of bars, pipes, lumber and more by using Add-On units for continuous runs. Sturdy steel **Starter Units** include 2 uprights, one set of bracing and 6 arm levels. **Add-On Units** include 1 upright, 1 set of bracing and 6 arm levels. Use **Single Sided** for against the wall storage and **Double Sided** to allow access from both sides. **2,000 lb. capacity per level**, 500 lb. per arm. 10"H clearance between arms. Blue enamel finish. 84"W x 39"D x 81"H.

STARTER		ADD-ON	
Model	Price	Model	Price
SINGLE SIDE			
FD245648	\$442.95	FD245650	\$244.95
DOUBLE SIDE			
FD245649	549.00	FD245651	294.95

WALL MOUNT BAR RACK



AS LOW AS
\$57

**1000 lb.
capacity**

Stores bar stock, lumber and more. Steel pipe rack includes 7 arms: three 15" arms with a 9"H clearance and four 12" arms with a 7 1/4"H clearance. 1,000 lbs. total capacity. Attractive, zinc plating. Easy assembly. Measures 60"H and weighs only 25 lbs. Sold in single units (Shown with one pair).

Model	Price Each	
	1-3	4+
FD652100	\$59.95	\$57.00

HORIZONTAL BAR RACK & CART

**2000 lb.
capacity**



FD652101



FD652132

Stores or transports lumber, pipes, conduit cables and wiring. Zinc-plated frame features 7 pairs of arms that extend 12" and fixed on 7 1/4" centers. Measures 36"W x 66"H. **2000 lb. capacity.** **Cart** has blue powder coat base with 5" poly-on-steel casters (2 swivel, 2 rigid). Easy assembly.

Model	Style	Price Each	
		1-3	4+
FD652101	Rack	\$102.95	\$97.00
FD652132	Cart	359.95	341.95