

Features

- Frosted lens to reduce glare
- Instant on to full brightness
- Energy efficient
- Wide light distribution
- High efficacy at 123-125 lumens per watt
- Light weight for easy installation
- Lower maintenance costs
- Available 3000K, 4000K, and 5000K color temperatures
- IP65 Rated for wet locations
- Operating temp -40°C - +60°C
-40°F - +140°F
- Dimensions 21.6" x 21.6" x 5.20"
- Field replaceable modular driver
- LM79/80 report and TM21 data available

- Superior heat management yields 60,000 hours life
- 0-10 V DC dimming standard
- UL, RoHS and FCC certified
- 7 year warranty
- Input voltage 120-277V
- Workable Voltage at 90-305V

Applications

- Offices
- Warehouses
- Storage areas
- Retail stores
- Malls
- Convention centers
- Airports
- Healthcare facilities
- Workshops
- Manufacturing plants
- Stadiums

Available Options

- 6' cord and twist lock plug
15A 120/277V
- 5' Aircraft cable
- Stainless Steel
Wire Guard
- Occupancy Sensor
- Pendant hook

Items Stocked in Illinois Warehouse


Model#	SKU	Lumens	CRI	Weight (lbs)	Color Temp (K)	Watts	Lumens Per Watt	Wattage Equivalent	IES File
52000	HB-18L-40K-UL	17,848	>80	14.5	4000	145	123	400 HID	
52001	HB-18L-50K-UL	18,332	>80	14.5	5000	146	125	400 HID	



Model 52050



NUWAVE Alset LED lighting, a product of Nuwave 52050

Light Distribution Curve [Unit: cd]

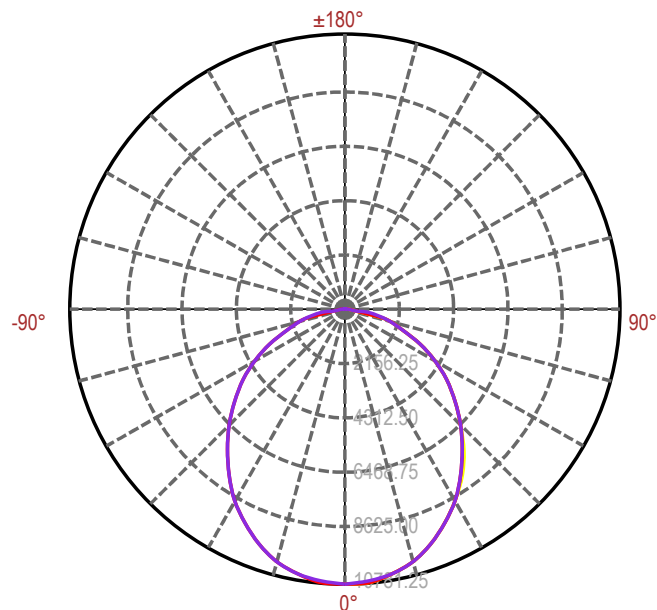

NUWAVE Alset LED lighting, a product of Nuwave 52050

Lux distance Curve

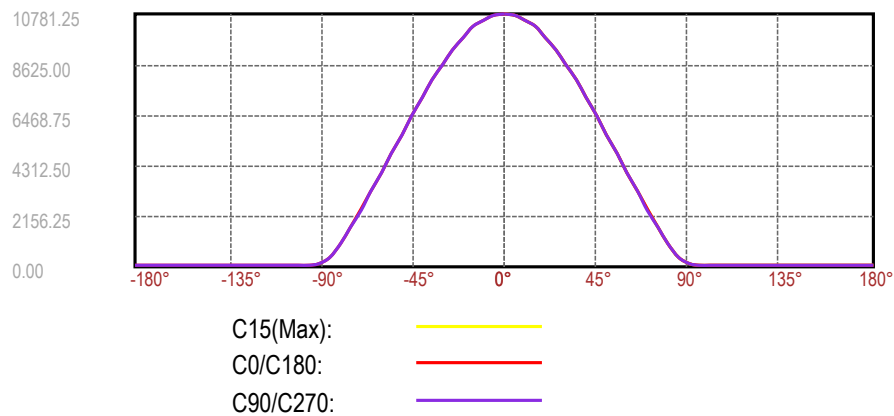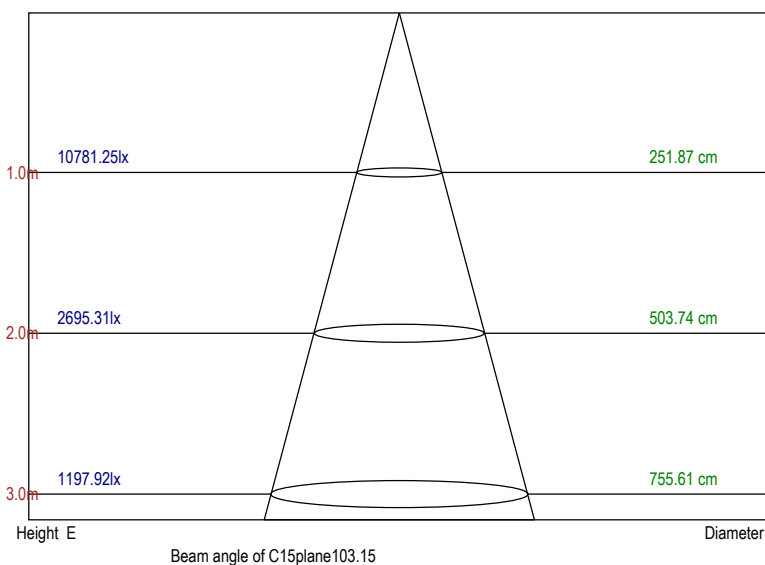

Equipment: LC-I-902 GMS-2000
Temperature(°C): 25.0


Date: 2015-06-11
Humidity(%): 65.0%

Operator: Liangzp
Distance(m): 29.89

Model 52051



NUWAVE Alset LED lighting, a product of Nuwave 52051

Light Distribution Curve [Unit: cd]

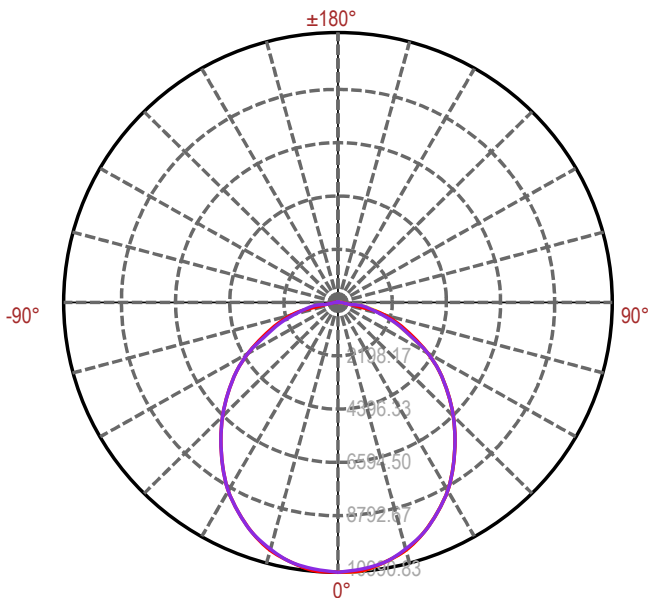

NUWAVE Alset LED lighting, a product of Nuwave 52051

Lux distance Curve

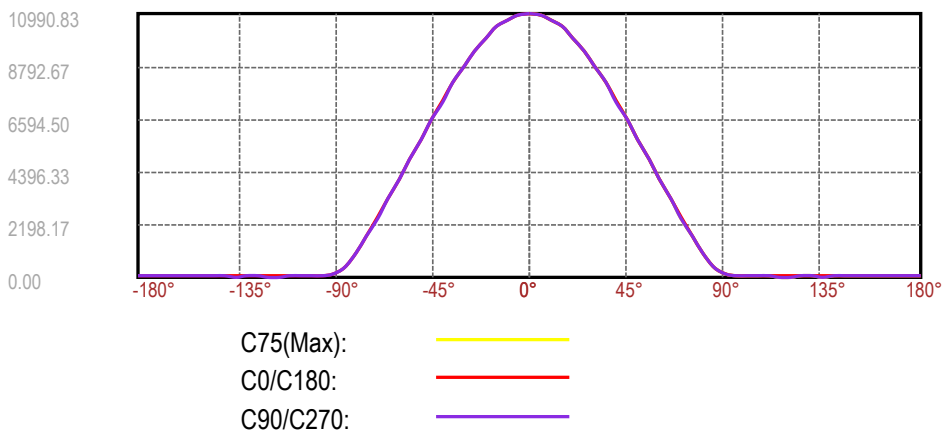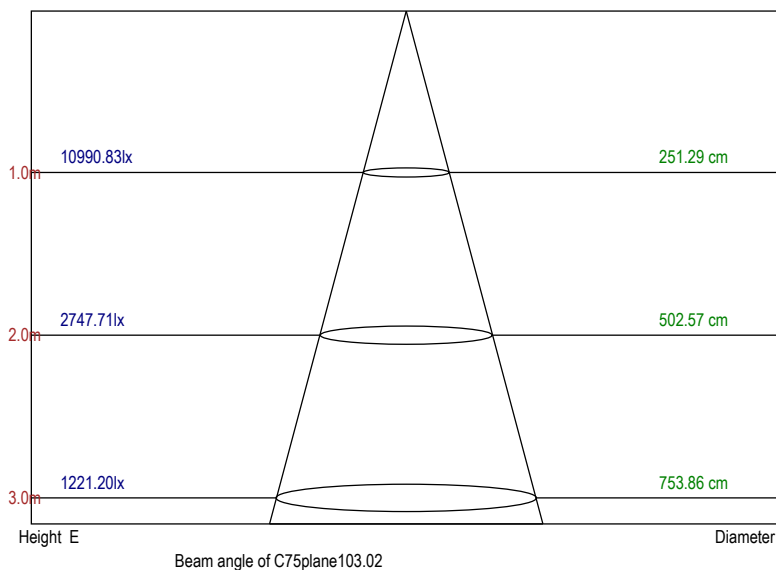

Equipment: LC-I-902 GMS-2000
Temperature(°C): 25.0

Date: 2015-06-11
Humidity(%): 65.0%

Operator: Liangzp
Distance(m): 29.89