



BEVERAGE-AIR

3779 Champion Blvd., Winston-Salem, NC 27105
1-888-845-9800 Fax# 1-336-245-6453
<http://www.Beverage-Air.com>

Commercial Refrigeration Equipment General Specification

3 Year Parts/Labor Warranty Additional 2 Year Compressor Warranty

DW FROSTY BREW COOLERS

Deep Well horizontal Frosty Brew coolers include 4 (four) self-contained models in widths of 50", 65", 80" and 95".

CABINET CONSTRUCTION

Exteriors of Deep Well models include attractive, wear-resistant vinyl on steel in black finish.

Bottle cap opener and cap catcher is standard with all models.

Tops include easy glide, stainless steel lids and stainless steel counter top with integral drinking glass stops. Lid locks are optionally available.

Standard interior metal is galvanized steel. Adjustable dividers included are epoxy coated steel wire.

Foamed-in-place CFC and HCFC-free polyurethane insulation enhances the structural strength of the cabinet and helps increase energy efficiency.

REFRIGERATION

Frosty Brew coolers let you serve better tasting—thirst quenching ice cold (30°F—32°F) beverages every time. Constructed with high cooling RPM fans which provide fastest cooling (pull down) and ice cold temperature of contained beverages for pure, thirst quenching enjoyment.

Balanced, forced-air, lift-out refrigeration system uses R134A refrigerant, which is CFC and HCFC-free for compliance with environmental safety concerns.

Coolers feature oversized self-defrosting evaporator with dual fans to move air and larger coil for greater cooling capacity.

ELECTRICAL

Units wired at factory and ready for connection to a 115/60/1 phase, 15 amp dedicated outlet. 8' long cord and plug set included.

Item No. _____
Quantity _____



MODELS:
DW49-B-29
DW64-B-29
DW79-B-29
DW94-B-29



DW49-B-29



DW64-B-29



DW79-B-29



DW94-B-29



*Note: Not all markings may apply to all model variations.

Available From:

Model Specified _____	Store# _____
Location _____	Quantity _____




Deep Well Horizontal Bottle Coolers
Models: DW49-B-29, DW64-B-29, DW79-B-29, DW94-B-29

ELECTRICAL CONNECTION
 Units pre-wired at factory and include 8' long cord and plug set.




MODEL	DW49-B-29	DW64-B-29	DW79-B-29	DW94-B-29
EXTERNAL DIMENSIONAL DATA				
Length Overall (inches)	50"	65"	80"	95"
Length Overall (mm)	1270	1651	2032	2413
Depth Overall (inches)	26 1/2"	26 1/2"	26 1/2"	26 1/2"
Depth Overall (mm)	673	673	673	673
Height Overall—(inches)	33 7/8"	33 7/8"	33 7/8"	33 7/8"
Height Overall—(mm)	860	860	860	860
Number of lids	2	2	3	4
INTERNAL DIMENSIONAL DATA				
NET Capacity (cubic ft.)	13.3	18.5	24.1	29.5
NET Capacity (Liters)	377	524	682	835
Internal Length Overall (inches)	46"	61"	76"	91"
Internal Length Overall (mm)	1168	1549	1930	2311
Internal Depth Overall (inches)	22 1/2"	22 1/2"	22 1/2"	22 1/2"
Internal Depth Overall (mm)	572	572	572	572
Internal Height Overall (inches)	27"	27"	27"	27"
Internal Height Overall (mm)	686	686	686	686
Number of dividers	3	4	5	6
12 oz. bottle capacity	17 1/2 cases	25 1/4 cases	32 cases	39 cases
12 oz. can capacity	23 3/4 cases	34 3/4 cases	45 3/4 cases	55 3/4 cases
ELECTRICAL DATA				
Full Load Amperes 115/60/1	7.3	7.8	9.5	9.5
ENERGY CONSUMPTION (KWH)				
	3.7	5.27	3.77	4.73
REFRIGERATION DATA				
Horsepower	1/4	1/3	1/2	1/2
WEIGHT DATA				
Gross Weight (Crated lbs)	280	317	422	446
Gross Weight (Crated kg)	127	144	191	202


PLAN VIEWS

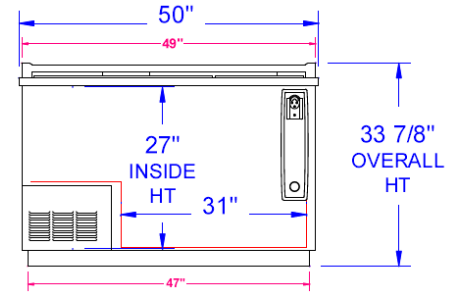


DW49 FRONT

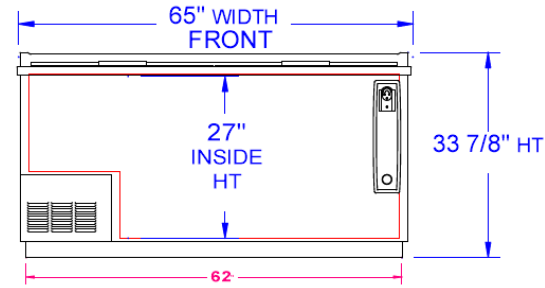


DW64 FRONT

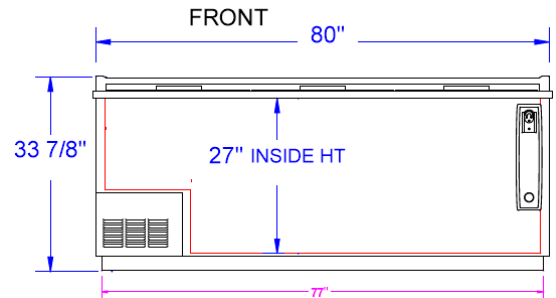

DW79 FRONT

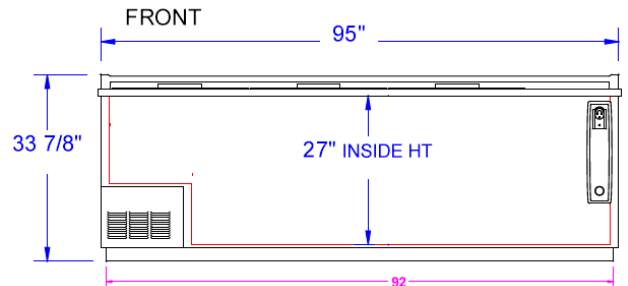

DW94 FRONT

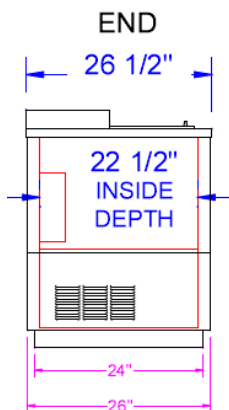

COMMON END



*Note: Not all markings may apply to all model variations.

BEVERAGE-AIR® CORPORATION

3779 Champion Blvd. • Winston-Salem, NC 27105 USA • (336) 245-6400 • Fax (336) 245-6453 • (888) 845-9800 • www.beverage-air.com

Specifications are subject to change without prior notice. 06/13