



FF1532B



34" x 14.75" x 22.75" (H x W x D)

15" wide all-refrigerator for built-in or freestanding use, with digital controls, LED light, lock, and black exterior finish; replaces FF1538B

Highlights:

Just under 15" wide for an easy fit, with a flush back design to save space

Flexible design allows built-in or freestanding use under counters

Digital thermostat offers precise and convenient temperature control

Factory-installed lock provides security you can count on

Product Features:


| | |
|------------------------------|--|
| Built-in capable | Make the best use of space by installing your appliance under the counter |
| Fully finished black cabinet | Allows the unit to be used freestanding |
| Factory installed lock | Keyed security on the door |
| Digital thermostat | Electronic controls for precise temperature management. |
| Digital display | Temperature readout can be shown in Celsius or Fahrenheit |
| LED lighting | Gentle illumination with an on/off switch |
| Automatic defrost | No-frost operation ensures reduced maintenance |
| Adjustable glass shelves | Rearrange refrigerator space to accommodate all sizes or remove shelves for simple cleanup |
| Door storage | Two chrome shelves offer the perfect storage solution for tall bottles and condiments |



FF1532B Specifications:


| Overview | |
|----------------------------|-----------------------|
| Height | 34.0" |
| Width | 14.75" |
| Depth | 22.75" |
| Depth with Handle | 24.63" |
| Depth with door at 90° | 36.25" |
| Capacity | 3.0 cu.ft. |
| Defrost Type | Frost-Free |
| Door | Black |
| Cabinet | Black |
| US Electrical Safety | ETL |
| Canadian Electrical Safety | ETL-C |
| Sanitation | ETL-S |
| Energy Usage/Year | 255.0kWh/year |
| Amps | 1.4 |
| Voltage/Frequency | 115 V AC/60 Hz |
| Weight | 63.0 lbs. |
| Shipping Weight | 77.0 lbs. |
| Parts & Labor Warranty | 1 Year |
| Compressor Warranty | 5 Years |
| Refrigerator Features | |
| Door Swing | RHD |
| Reversible | Yes |
| Shelf Type | Glass |
| Shelf Qty | 3 |
| Full Door Shelf Qty | 2 |
| Adjustable Shelves | Yes |
| Thermostat Type | Digital |
| Fan Type | Interior and Exterior |
| Refrigerant Type | R600a |
| Refrigerant Amount | 0.64 |
| High Side PSI | 270.0 |
| Low Side PSI | 105.0 |
| Level Legs Qty | 4 |
| Interior Light | Yes |
| Dimensions | |
| Interior Height | 24.63" |
| Interior Width | 12.0" |

| | |
|------------------------|--------|
| Interior Depth | 17.63" |
| Compressor Step Height | 3.13" |
| Compressor Step Width | 12.0" |
| Compressor Step Depth | 5.25" |

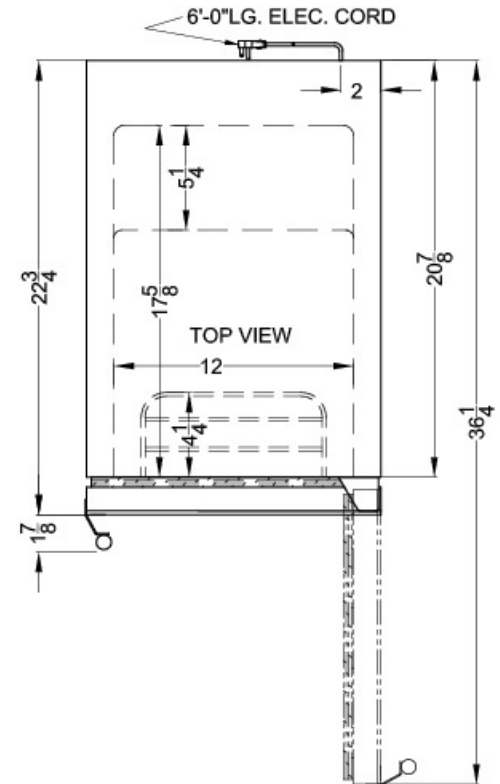

SUMMIT APPLIANCE DIVISION FELIX STORCH, INC.

770 Garrison Avenue, Bronx, NY 10474 USA TEL 718-893-3900 FAX 844-478-8799 info@summitappliance.com www.summitappliance.com

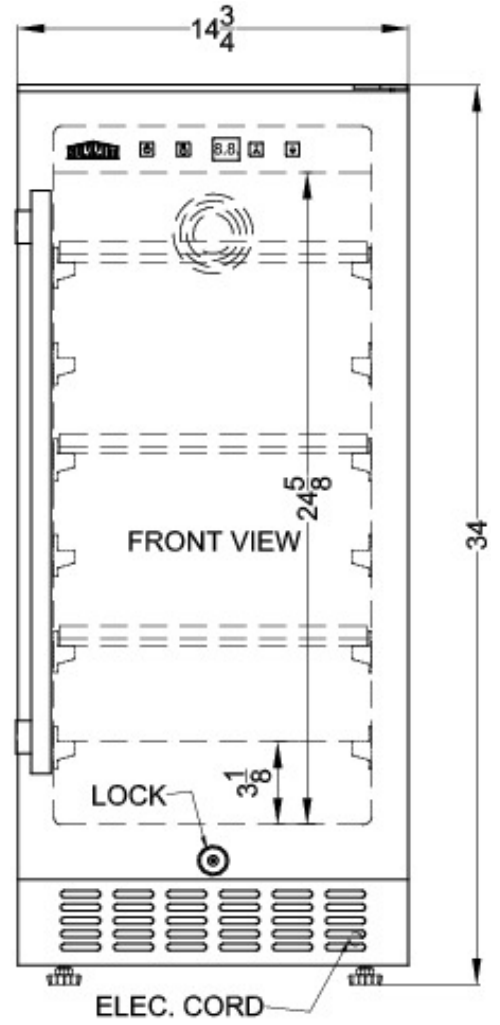

SUMMIT APPLIANCE DIVISION FELIX STORCH, INC.

770 Garrison Avenue, Bronx, NY 10474 USA TEL 718-893-3900 FAX 844-478-8799 info@summitappliance.com www.summitappliance.com