

**TURBO AIR** REFRIGERATOR MANUFACTURER  
**Turbo air**  
 more durable, efficient, beautiful

4184 E. Conant St.  
 Long Beach, CA 90808  
 Tel. 310-900-1000  
 Fax. 310-900-1077  
[www.turboairinc.com](http://www.turboairinc.com)

Project :	
Model # :	
Item # :	Qty :
Available W/H :	
Approval :	

## Sakura Sushi Case

Display Cases  
 Refrigerated Sushi Cases

*Its innovative design and new technology will position Turbo Air as the leader in sushi case products for many years to come*

**Model : SAKURA-50-L  
 SAKURA-50-R**



**SAKURA-50-R**



Unique and Stylish  
 304 Stainless Steel Material

### ≡ FEATURES & BENEFITS ≡

- Refrigerator maintains 35°F ~ 41°F for the best in food preservation
- Ambient temperature range 50°F ~ 80°F, saturation temperature 39°F
- Beautifully curved, angled down top front glass
- Equipped NSF approved thermometer
- 1" diameter drain hole with plastic cover
- Slightly tilted bottom for better drainage
- Larger interior for optimized display effect
- 304 stainless steel solid food plates
- Oversized and balanced CFC free R-134A refrigeration system
- Tempered glass doors with durable plastic door handles at chef side
- Exterior body is beautifully made from unique and stylish 304 stainless steel material
- Side mount compressor makes it easy to be serviced without being moved
- Elegant contemporary Euro design enhances any store application
- Easy cleaning and excellent durability
- Condenser locates on left or right from the front view
- Drain hole locates on left from the chef side
- Recommended operating conditions  
 SAKURA models are designed to operate in environments where temperature & humidity do not exceed 75°F and 55% relative humidity.



Model	Compressor Location	Sliding Door	CU./FT.	Bottom Shelves	HP	AMPS	Crated Weight (lbs.)	L x D* x H (inches)
SAKURA-50-L SAKURA-50-R	Left Right	2	1.3	3	1/6	3	88	48 1/4 x 14 1/8 x 11 1/2

# Sakura Sushi Case

Display Cases  
Refrigerated Sushi Cases

## Model : SAKURA-50-L SAKURA-50-R


ELECTRICAL DATA	
Voltage	115/60/1
Plug Type	Ⓜ NEMA 5-15P
Full Load Amperes	3
Compressor HP	1/6
Cord Length ft.	9
Refrigerant	R-134A
DIMENSIONAL DATA	
Net Capacity cu. ft.	1.3
Ext. Length Overall in.	48 1/4 (1226mm)
Ext. Depth Overall in.*	14 1/8 (360mm)
Ext. Height Overall in.	11 1/2 (292mm)
Int. Length Overall in.	33 1/4 (845mm)
Int. Depth Overall in.	12 (305mm)
Int. Height Overall in.	6 1/2 (165mm)
# of Sliding Doors	2
# of Bottom Shelves	3
Net Weight lbs.	76
Gross Weight lbs.	86

Design and specifications subject to change without notice.  
Actual shipping weight may differ due to extra packing materials for product protection.  
\* Depth does not include 5/8" for drain.


- **WARRANTY :** 1 Year Parts and Labor Warranty  
Additional 4 Year Warranty on Compressor
- **Self-contained system**
- **No plumbing required**
- **Simple plug-in installation**

## PLAN VIEW

(unit : inch)

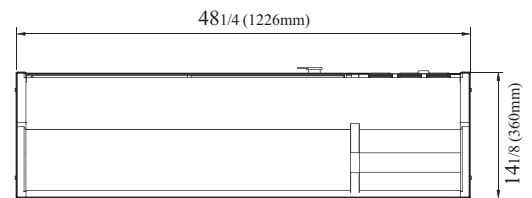


SAKURA-50-R

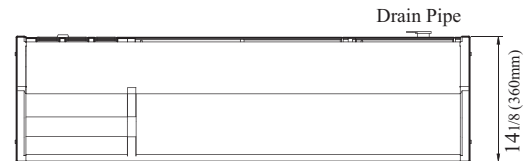


SAKURA-50-L

## TOP VIEW

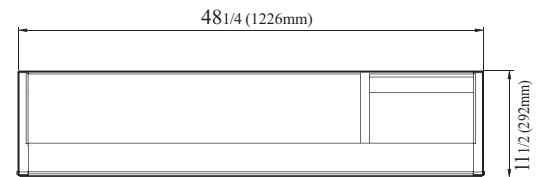


SAKURA-50-R

 

SAKURA-50-L

## FRONT VIEW

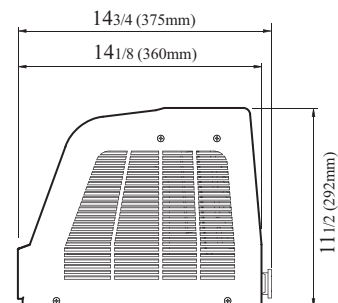

## SIDE VIEW

Ver.201501



- Turbo Air : 800-627-0032
- GK : 800-500-3519
- Warranty : 800-381-7770
- AC : 888-900-1002

REFRIGERATOR MANUFACTURER  
**Turbo air**

**GERMAN KNIFE**

**RADIANCE**

**GREEN WORLD**

AIR CONDITIONER MANUFACTURER  
**Turbo air**