


# QF O-rings, Black and Red 3262

Size (ID) In.	Std Weight Lbs	Cord Dia. mm
3	0.01	7
4	0.02	7
5	0.03	7
6	0.04	7
7	0.08	9
8	0.09	9
9	0.10	9
10	0.11	9
11	0.17	9
12	0.22	11
13	0.23	11
14	0.25	11
15	0.26	11
16	0.27	11
17	0.28	11
18	0.29	11
20	0.30	11
22	0.31	11
24	0.33	11

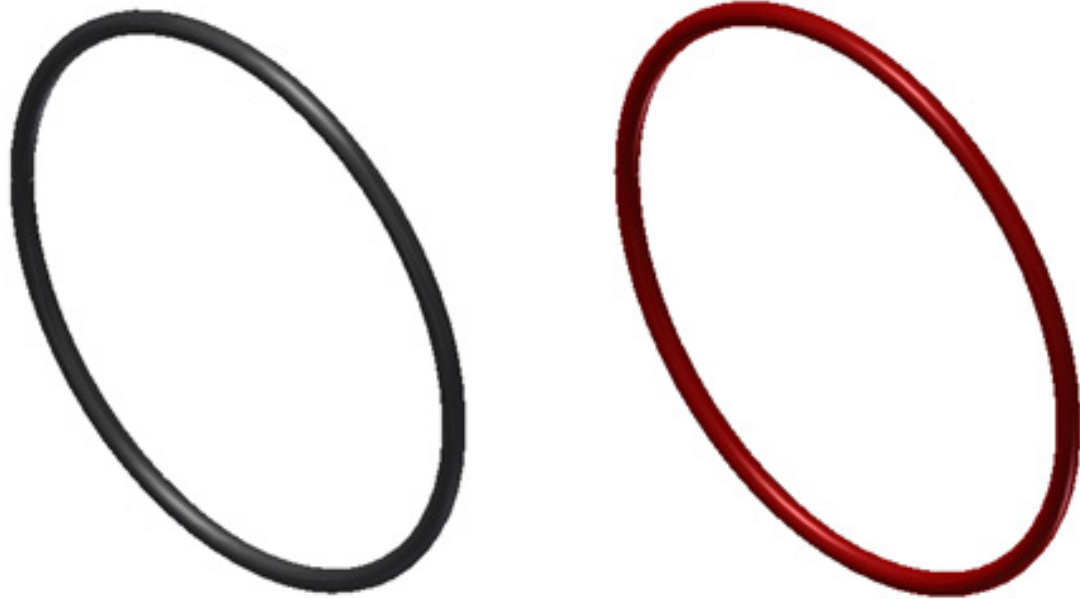

O-ring	Temp Rating	Additional Notes
Black O-ring	-40° to 250°	Included with adjustable nipple as standard
Red O-ring	-75° to 450°	<b>Optional</b> - for higher temperatures and FDA approval

Product	Material	Compliance / Rating
Black O-ring	Buna-N, 60 durometer hardness	
Red O-ring	Silicone rubber, 70 durometer hardness	ZZ-R-765 Class 2A and 2B grade 70 AMS-3304E and 3304F and 3304G, FDA approved