



SPECIFICATION SHEET

34-225



G-TEK® NPG SEAMLESS KNIT NYLON GLOVE WITH NITRILE COATED SMOOTH GRIP ON PALM & FINGERS

- Seamless one-piece nylon shell offers increased comfort, finger dexterity and breathability
- Solid Dipped Nitrile coatings provide excellent dry grip and will not absorb liquids into the coating
- Knit Wrist helps prevent dirt and debris from entering the glove
- This style is also available tri-folded and shrink-wrapped for carefree dispensing through vending machines (34-225V)

APPLICATIONS

Ideal for manufacturing and assembly applications where abrasion, cut, and puncture resistance is required.

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)


TECHNICAL DATA

MATERIAL	Nylon with nitrile coating on palm and fingers				
COLOR	<input type="checkbox"/> White / <input checked="" type="checkbox"/> Gray				
CUFF STYLE	Continuous Knit				
SIZES	XS - XL				
PACKAGING	12 pairs per dozen, 25 dozen per case				
CASE	XS: 20.1" x 9.8" x 20.1" / 51cm x 25cm x 51cm				
	S: 20.1" x 9.8" x 20.1" / 51cm x 25cm x 51cm				
	M: 20.9" x 10.2" x 20.9" / 53cm x 26cm x 53cm				
	L: 20.9" x 10.6" x 21.3" / 53cm x 27cm x 54cm				
	XL: 20.9" x 10.6" x 21.3" / 53cm x 27cm x 54cm				
CASE WEIGHT	XS	S	M	L	XL
	27.5 lbs 12.5 kg	30 lbs 13.6 kg	33 lbs 15 kg	35 lbs 15.9 kg	35 lbs 15.9 kg
COO	China				



DIMENSIONS (in/cm)

	XS	S	M	L	XL
A	7.9 / 20	8.9 / 22.5	9.4 / 24	9.8 / 25	10.2 / 26
B	3.2 / 8.2	3.3 / 8.5	3.5 / 9	3.7 / 9.5	3.9 / 10
H					

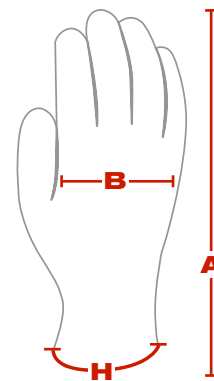

PERFORMANCE PROPERTIES

EN388: 4121						
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

BARCODES

ITEM	BAG	DOZEN	CASE
<input type="checkbox"/> 34-225/XS	--	01616314021206	02616314021206
<input type="checkbox"/> 34-225/S	--	01616314011467	02616314011467
<input type="checkbox"/> 34-225/M	--	01616314011474	02616314011474
<input type="checkbox"/> 34-225/L	--	01616314011481	02616314011481
<input type="checkbox"/> 34-225/XL	--	01616314011498	02616314011498

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.