



**VAN STORAGE SOLUTIONS**  
FOR THE WAY YOU WORK™

# INSTALLATION MANUAL

## MOUNTING CHANNEL KIT, 102 IN (2102-0-01)

ATTENTION: PLEASE READ AND UNDERSTAND ALL INSTRUCTIONS AND WARNINGS BEFORE ASSEMBLING, INSTALLING OR USING THIS PRODUCT.

### TOOLS REQUIRED

- RTV automotive/exterior sealant (not included)
- Anti-sieze (not included)
- 5MM Hex Key (for M8 mounting bolts)
- 1/2" in Socket or Wrench

### ! CAUTION

Be safe - always wear protective eyewear to keep debris out of your eyes when installing WEATHER GUARD® Van Products.


### PARTS LIST




10X 5/16" WASHER




8X M8X35MM BOLT

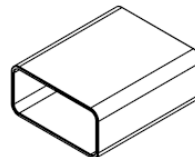

4X RED CAP

 

2X 5/8" BUMPER

 

2X 5/16"X1-1/4" BOLT



2X 5/16" NYLON LOCK NUT



8X 3/8" SPACER



2X MOUNTING CHANNEL

**ATTENTION: PLEASE READ AND UNDERSTAND ALL INSTRUCTIONS AND WARNINGS  
BEFORE ASSEMBLING, INSTALLING OR USING THIS PRODUCT.**

## **INSTALLATION INSTRUCTIONS**

### **GENERAL INSTRUCTIONS:**

The mounting channel kit includes mounting channels and hardware to attach the channels to the roof of a compact van using mounting holes or weld nuts provided by the OEM van manufacturer.

**STEP 1** Position mounting channels on roof of van aligning the holes and slots with OEM mounting points.

**STEP 2** During final assembly, apply RTV sealant (not included) to the van roof around the mounting points to prevent water from leaking into the vehicle.

**STEP 3** Attach red cap to ends of mounting rails.

**STEP 4** Apply anti-seize (not included) to mounting bolts.

**STEP 5** Attach the mounting channels to the van using the washers and mounting bolts.

### **VEHICLE SPECIFIC INSTALLATION NOTES:**

#### **FORD TRANSIT 130 IN WHEEL BASE:**

Ford provides M8 weld nuts in the roof of the Transit. First, remove the plastic caps plugging the mounting holes. Clean excess paint from the threads of the weld nuts.

Because of the roof design, there is a small gap between the roof and the front of the mounting channel. Weather Guard does not recommend installing blind fasteners into the roof over the passenger compartment. Instead, to provide a solid support for the front of the mounting channel, attach the Bumpers to the underside of the channel using two each of the 5/16-18 x 1-1/4 in mounting bolt, the 5/16 in washer, and the 5/16-18 lock nuts. Position the bumper as close to the front end of the rail as possible. Tighten to 10 ft-lbs.

When attaching the mounting channels to the Transit roof, position the 3/8 in spacers on the roof over the weld nuts, sealing them in place with RTV sealant. Use more RTV sealant between the mounting channel and the spacer. Use the M8 bolts and 5/16 in washers and insert them through the mounting channel and spacer and into the Transit roof weld nuts. Tighten bolts to 17 ft-lbs by hand or with a torque-settable driver. Avoid using an impact wrench.

#### **FORD TRANSIT 158 IN WHEEL BASE (REGULAR and EXTENDED BODY):**

Ford provides M8 weld nuts in the roof of the Transit. First, remove the plastic caps plugging the mounting holes. Clean excess paint from the threads of the weld nuts.

Bumpers are not needed on 158 in wheel base Transit vans.

When attaching the mounting channels to the Transit roof, position the 3/8 in spacers on the roof over the weld nuts, sealing them in place with RTV sealant. Use more RTV sealant between the mounting channel and the spacer. Use the M8 bolts and 5/16 in washers and insert them through the mounting channel and spacer and into the Transit roof weld nuts. Tighten bolts to 17 ft-lbs by hand or with a torque-settable driver. Avoid using an impact wrench.

## WARNING

This product is only intended and safe for use in storing and transporting small tools, equipment and other similar materials. These instructions are to be followed using the parts and fasteners supplied for proper installation. Any modifications or improper installation of this product will create a hazardous condition that could result in death, serious personal injury and/or property damage.

All floor mounting bolts near the fuel tank area should be installed from the underside of the vehicle, to guard against the fuel tank being punctured in the event of a collision. This would mean not using Blind Fasteners in this area. Holes in this area should be 5/16". Ensure ample space in roof ribs and sidewall ribs for mounting screws so as not to puncture exterior roof or wall.

Do not install this product where it could interfere with deployment of air bags. Failure to comply could result in death or serious body injury.

## - NOTICE -

Any modification or unintended use of this product shall immediately void all manufacturers warranties. Manufacturer disclaims all liability for injuries to persons or property resulting from any modification to, or unintended use of this product.

## KNAACK LLC LIMITED LIFETIME WARRANTY FOR WEATHER GUARD® PRODUCTS

WEATHER GUARD® Products — Limited Lifetime Warranty (Purchased on or after 1/1/2009)

Knaack LLC (the "Manufacturer") warrants to the original purchaser only that WEATHER GUARD® Truck and Van Products (the "WEATHER GUARD® Product") will be free from defects in material and workmanship from the date of purchase and continuing for the expected lifetime of the WEATHER GUARD® Product. A copy of the original sales receipt must be supplied to the Manufacturer at the time a warranty claim is made. This warranty terminates if the original purchaser transfers the WEATHER GUARD® Product to any other person.

### What is Covered

All WEATHER GUARD® Products identified above that are purchased on or after January 1, 2009.

### What We Will Do to Correct Problems

Subject to the limitations and exclusions described in this limited warranty, the Manufacturer will remedy defects in materials or workmanship by providing one of the following remedies at its option and without charge to the original purchaser for parts or labor: (a) repairing the defective portion of the WEATHER GUARD® Product or (b) replacing the entire WEATHER GUARD® Product. In addition, the manufacturer may elect at its option, not to repair or replace the WEATHER GUARD® Product, but rather issue to the original purchaser a refund equal to the purchase price paid for the WEATHER GUARD® Product or a credit to be used toward the purchase of new WEATHER GUARD® Product.

### What is Not Covered

This limited warranty expressly excludes:

- Defects caused by normal wear and tear, cosmetic rust, scratches, accidents, unlawful vehicle operation, or modification to the product, or any types or repair of a WEATHER GUARD® Product other than those authorized or provided by the Manufacturer.
- Defects resulting from conditions beyond the Manufacturer's control including, but not limited to misuse, overloading, or failure to assemble, mount or use the WEATHER GUARD® Product in accordance with the Manufacturer's written instructions or guidelines included with the WEATHER GUARD® Product or made available to the original purchaser.
- Damage to the contents of the box or vehicle.
- TO THE EXTENT PERMITTED BY LAW, IN NO EVENT SHALL THE MANUFACTURER BE LIABLE FOR ANY INCIDENTAL, SPECIAL, INDIRECT, OR CONSEQUENTIAL DAMAGES, INCLUDING ANY ECONOMIC LOSS, WHETHER RESULTING FROM NONPERFORMANCE, USE, MISUSE OR INABILITY TO USE THE WEATHER GUARD® PRODUCT OR THE MANUFACTURER'S NEGLIGENCE.

### No Other Express Warranty Applies

This Limited Lifetime Warranty is the sole and exclusive warranty for WEATHER GUARD® Products. No employee, agent, dealer, or other person is authorized to alter this warranty or make any other warranty on behalf of Knaack LLC.

### Notification Procedures

If the WEATHER GUARD® Product does not conform with the terms of this limited warranty, the original owner must promptly notify the Manufacturer in writing upon discovery of the nonconformity. In order to receive the remedies under this limited warranty, the warranty claim must describe the nature of the nonconformity, and a copy of the original sales receipt, invoice, bill or other proof of purchase must accompany the claim. Repairs or modifications made to the WEATHER GUARD® Product by other than the Manufacturer or its authorized agent will nullify this limited warranty. Coverage under this limited warranty is conditioned at all times upon the owner's compliance with these required notification and repair procedures. Warranty claims must include reciprocal contact information and may be made via certified mail to:

Knaack LLC ATTN: Warranty Claims  
420 E. Terra Cotta Avenue Crystal Lake, IL 60014

If you have any questions, please call toll free at 1-800-456-7865.

©2013 Knaack LLC

