



4700 W. 160th St.  
Cleveland, OH 44135  
PH:800-321-9532  
FX:800-321-9535  
www.oatey.com


**TECHNICAL SPECIFICATION**

**THERMOPLASTIC (CANADIAN)  
BASE NO-CALK ROOF  
FLASHINGS**



**Engineering Specification:** Oatey Thermoplastic Canadian Color Flashings can be used in commercial and residential applications where a watertight seal for roof penetrations around the plumbing vent pipe is required. Colors come in Black, Brown, Grey, and Weatherwood.


**Job Reference**

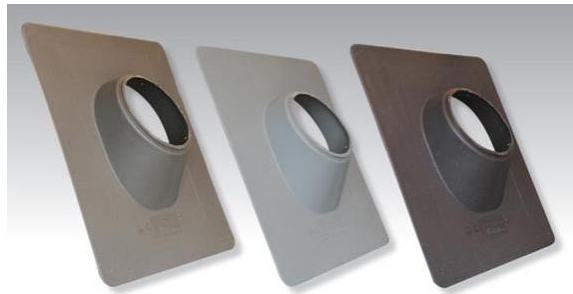

Weatherwood      Grey      Brown

(All dimensions in inches)

- ◆ Roof Flashing slides over vent pipe for pitch to 45°
- ◆ Non-fading, non-cracking rigid thermoplastic base
- ◆ Non-fading sealing collar
- ◆ Approved for Type B installations
- ◆ Not for hot-mopped or built-up roofs

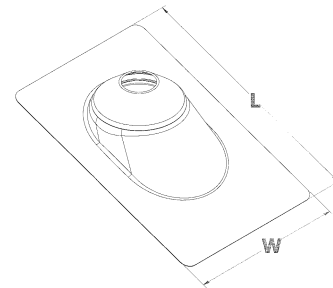

✓	Product No.	Description	Length (L)	Width (W)	PACK	CARTON WEIGHT
	48100	1-1/4"- 1-1/2" Thermoplastic Black No-Calk Roof Flashing	16	14	12	6 lbs.
	48101	2" Thermoplastic Black No-Calk Roof Flashing	16	14	12	6 lbs.
	48102	3" Thermoplastic Black No-Calk Roof Flashing	16	14	12	8 lbs.
	48103	4" Thermoplastic Black No-Calk Roof Flashing	16	14	12	9 lbs.
	48080	1" Thermoplastic Brown	16	14	12	6 lbs.
	48081	2" Thermoplastic Brown	16	14	12	6 lbs.
	48082	3" Thermoplastic Brown	16	14	12	8 lbs.
	48083	4" Thermoplastic Brown	16	14	12	9 lbs.
	48084	1" Thermoplastic Grey	16	14	12	6 lbs.
	48085	2" Thermoplastic Grey	16	14	12	6 lbs.
	48086	3" Thermoplastic Grey	16	14	12	8 lbs.
	48087	4" Thermoplastic Grey	16	14	12	9 lbs.
	48088	1" Thermoplastic Weatherwood	16	14	12	6 lbs.
	48089	2" Thermoplastic Weatherwood	16	14	12	6 lbs.
	48090	3" Thermoplastic Weatherwood	16	14	12	8 lbs.
	48091	4" Thermoplastic Weatherwood	16	14	12	9 lbs.

Data is subject to manufacturing tolerances.