

PROTEKT™ STAND

30600-SAE


The 30600-SAE has extra wide adjustable kneepads that will help meet a wider range of patient needs. To support the extra weight, the 30600-SA has a heavy duty boom to help lift and support the patient for smoother and safer transfers. The emergency quick release makes the 30600-SAE the safest lift in any situation.

- 600 pound capacity with manual emergency lowering.
- Fast speed lift motor reduces time for the transfer.



- 6 sling hooks allow for multiple sling options and a wider range of transfers.
- Battery lasts twice as long as competing options for less downtime (24 volts).
- Ergonomically designed foot pedal base opening (no clumsy hand lever).
- Clip free sling hookups improve safety and reduce downtime.
- Full parts breakdowns and modular design on lift and electronics.
- Advanced electronics with auxiliary up/down lift controls.

| DIMENSIONS

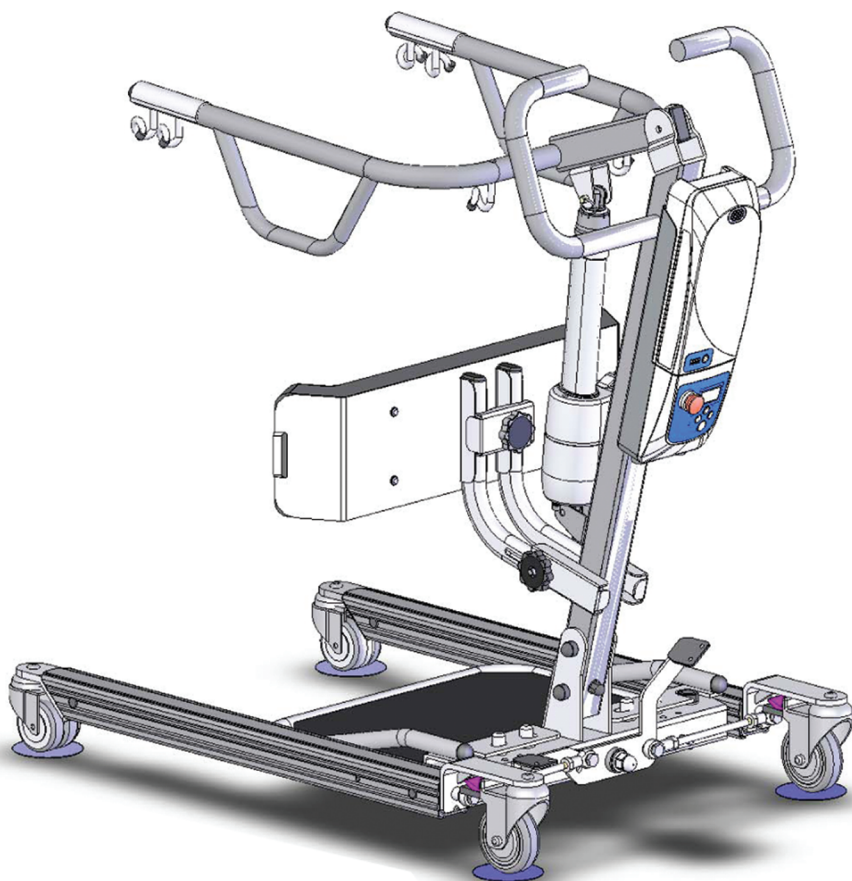

SPECIFICATIONS FOR 300600-SAE

maximum capacity	600lb
base legs length	40"
external width	26"
expandable internal width	38"
base height	4.7"
min. lifting height	35"
max. lifting height	70"
internal width	19"

* SPECIFICATIONS PROVIDED ARE A GENERAL GUIDELINE
AND ARE SUBJECT TO CHANGE WITHOUT NOTICE



270 Washington Street Mount Vernon, NY 10553

Tel: 855-BE-PROACTIVE (855-237-7622) • Fax: 845-205-6005

www.proactivemedical.com • sales@proactivemedical.com

