

8 Ch. Plug & Play Network Video Recorder and IP Camera Kit

ZIPL84D2

8 Channel NVR with 8 Channel Built-In PoE, 2TB
4 Full HD 1080p Outdoor IR Dome Cameras

ZIPL84B2

8 Channel NVR with 8 Channel Built-In PoE, 2TB
4 Full HD 1080p Outdoor IR Bullet Cameras

ZIPL88D2

8 Channel NVR with 8 Channel Built-In PoE, 2TB
8 Full HD 1080p Outdoor IR Dome Cameras

ZIPL88B2

8 Channel NVR with 8 Channel Built-In PoE, 2TB
8 Full HD 1080p Outdoor IR Bullet Cameras

ZIPL8BD2

8 Channel NVR with 8 Channel Built-In PoE, 2TB
4 Full HD 1080p Outdoor IR Dome Cameras,
4 Full HD 1080p Outdoor IR Bullet Cameras




Front panel



Rear panel

ZIPL8BD2 shown

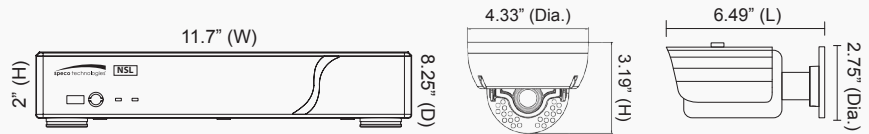

NVR Features

EZ Wizards

- Camera: quickly discovers and installs IP cameras
- Setup: for quick system setup
- Network: network setup and port forwarding
- Record: quickly setup recording resolutions and recording type

EZ Search: quickly search events from thumbnails

EZ Copy: auto copy what you are playing onto a USB flash drive

- Built-In PoE IEEE 802.3af
- Video Out: 1 HDMI®, 1 VGA
- Plug & play feature with Speco's IP cameras
- Dual network ports for isolating IP camera network and remote network traffic
- Network video recorder with free Speco DDNS server
- Digital Deterrent® for triggering audio message via motion detection or sensor
- Full HD (1920 x 1080) recording and playback

- Switch between low and high quality stream during simultaneous Continuous + Motion or Continuous + Sensor recording modes for storage optimization
- Built-in S.M.A.R.T. Technology (Self-Monitoring, Analysis and Reporting Technology for HDD)
- Remote monitoring / recording / playback / configuration / software upgrades and PTZ control via internet
- Supports multiple PC based browsers such as Internet Explorer, Google Chrome, Firefox and Safari
- Network accessible via SpecoTech Multi-Client Software, SecureGuard® VMS and Speco Player Mobile Viewer
- IR remote control and mouse included
- PC and MAC® compatible
- 3 year warranty

Camera Features

- Full HD 1080p @ 30fps
- Max 3MP @ 20fps
- 2.8mm fixed lens
- Standard PoE
- True Day/Night operation
- IR LED operation
- IP67 compliant
- 2 year warranty

Camera Specifications

Image Sensor 1/3" CMOS, 3MP
Max Resolution 2304x1296
Minimum Illumination.... 0 lux @F2.0 (IR on) / 0.37 lux @F2.0 (IR off)
S/N Ratio 50dB
Motion Detection..... Yes
Day/Night..... IR-cut filter
DNR..... 3D
IR Range 98' (depending on scene reflection)

Operating & Unit Specifications

Power SupplyPoE or 12VDC (power supply not included)
Power Consumption4W
Operating Temperature.....-20° F - 140° F
Camera Weight.....Dome: 1 lb. / Bullet: 13 oz.
Camera Dimensions.....Dome: 4.33" (Dia.) x 3.19" (H) / Bullet: 2.75" (Dia.) x 6.49" (L)
NVR Weight.....4 lbs.
NVR Dimensions 11.7" (W) x 2" (H) x 8.25" (D)

iPhone is a trademark of Apple Inc., registered in the U.S. and other countries. Android is a trademark of Google Inc. The terms HDMI and HDMI High-Definition Multimedia Interface, and the HDMI Logo are trademarks or registered trademarks of HDMI Licensing LLC in the United States and other countries. Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 8/4/16

Optional Accessories



ERS1V
Vented Rack Shelf

IRRPTKIT
IR Repeater Kit

Model		ZIPL84D2 / ZIPL84B2 / ZIPL88D2 / ZIPL88B2 / ZIPL8BD2	
Video	Input	Max. IP Channels	8
		Resolution	Max. 1920 x 1080
	Output	HDMI®	1 HDMI (1280 x 720, 1920 x 1080)
		VGA	1 VGA (1280 x 720, 1920 x 1080)
Audio	Input	IP Camera (Network)	8
	Output	Local Output (RCA)	1
	Audio Codec		G.711
Recording	Compression		H.264 (baseline, main and high profile)
	Resolution	1080p	240fps
		720p	240fps
	Recording Mode		Continuous / Motion / Sensor / Schedule / Manual / Continuous + Motion / Continuous + Sensor
	Pre-Recording		Max. 20 minutes
	Post Recording		Max. 60 seconds
Playback	Search		EZSearch, Date/Time, Event, Archive, Log
	Multi-Decoding		1, 4, 8
	Playback Speed		x0.25, x0.5, x2, x4, x8, x16, x32, x64
Backup	Media		USB Drive, External HDD, Network
	File Format		BMP, AVI, Proprietary Format
	Large Backup		Yes (max. 24 hours)
Storage	HDD	Capacity of 1 HDD	2TB
		Internal HDDs	1
	USB	Front	1
		Rear	1
User I/F	Input Method		IR, Mouse, Keyboard Controller
Event	Sensor In	IP Camera (Network)	8
		Local Input (Terminal Block)	None
	Local Alarm Output (Terminal Block)		None
	Motion Detection (From IP Camera)		Yes
Network	LAN (IP Camera, Auto Connection)		8 (802.3af PoE)
	WAN (IP Camera, Remote Access)		10/100Base-T
	Protocols		TCP/IP, UDP, DHCP, HTTP, NTP, SMTP, RTP, RTSP
	Max. Throughput		20Mbps
Network Access	Mobile Viewer		iPad® / iPhone® / Android™
	PC Web Viewer		Internet Explorer, Chrome, Firefox, Safari
	PC Client		SpecoTech Multi-Client Viewer and SecureGuard® VMS
	MAC Client		Speco Client for MAC and SecureGuard® VMS
	Remote Setup and Upgrade		Yes
Features	Digital Deterrent®		Default + up to 8 audio files
	Digital Zoom		Yes
	DLS (Daylight Savings)		Yes
	S.M.A.R.T		Yes
	Internal Beep		Yes
	Multi-Language		Yes
	Dynamic DNS		Yes (free Speco DDNS)
	Email Notification		Yes
NTP (Network Time Protocol)		Yes	
Power Source	Power Supply Voltage		48VDC, 2.0A
Allowable Operating Temperature		41° F - 104° F	
Allowable Storage Temperature		14° F - 122° F	
Weight	Unit Weight (Gross Weight)		4 lbs.
Dimensions	Unit Dimensions (W x H x D)		11.7" (W) x 2" (H) x 8.25" (D)

Please note that specifications and unit exterior design are subject to change without notification.