


# TPI Industrial Belt Drive Suspension Blowers

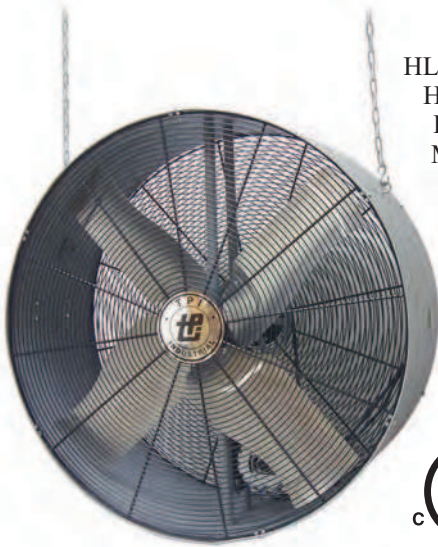

HL MODELS  
HAVE UL  
LISTED  
MOTOR



## Features

- On-Off rocker switch on 120V, 1 phase models
- SJT type 3 conductor, 12' long cord on 120V, 1 phase models
- No cord on dual voltage models
- Aluminum blade
- Powder coated front and rear guards
- Corrosion and dent proof high density polyethylene housing
- Powder coated spiral wire front and rear guards
- Meets OSHA standards
- 1 year limited warranty
- Mounting chain not included.

## Motor Specifications

- 120V., 1-Phase
- Ball bearing
- Permanent split capacitor
- 2-Speed on 30" & 36" model
- 1-Speed on 42" model
- Permanently lubricated

External junction boxes on dual voltage models allow units to be wired for either voltage without removing guards. Hazardous Location models have explosion proof motors and external junction boxes rated for Class I, Group D, & Class II, Groups E, F & G,. (Metal housing and no switch.)

## Standard Models

UPC#	MODEL	SIZE	MOTOR		CFM	RPM	AMPS	SHIP WT. (LBS.)
			TYPE	HP				
686334								
796552	SB 36-B	36"	115 V	1/2	14,500	500	8	120
796569	SB 42-B	42"	1 PH	3/4	18,200	430	11	135
796576	SB 48-B	48"	ODP	1	22,700	390	15	155
850988	SB 36-B-3	36"	230 / 460 V	1/2	14,500	500	2.3 / 1.1	127
850995	SB 42-B-3	42"	3 PH	3/4	18,200	430	3.3 / 1.5	143
851008	SB 48-B-3	48"	ODP	1	22,700	390	3.8 / 1.9	164
851015	SB 36-B-HL	36"	115 / 230 V	1/2	14,500	500	7.8 / 3.9	135
851022	SB 42-B-HL	42"	1 PH	3/4	18,200	430	10.8 / 5.4	150
851039	SB 48-B-HL	48"	EXP	1	22,700	390	13.2 / 6.6	173

Note: Products listed in this section are custom built and subject to 100% cancellation/restocking charges.  
Note: Photograph is a representation of stocked models. Actual model may vary slightly in appearance.