

8U and 12U Wall Mount Rack Installation Instructions

Step 1

Remove all contents from the box and make sure all of the following parts are accounted for.


Box Contents

- 1 Left Base
- 1 Right Base
- 6 Rail Screws (8 for 12U unit)
- 2 Pre-tapped Rails
- 1 Template Instruction Sheet

Tools Required



- Cross head screw driver
- Stud Finder
- Screw Gun
- Level

(You will also need mounting hardware specific to the type of wall you are mounting to. See step 3)

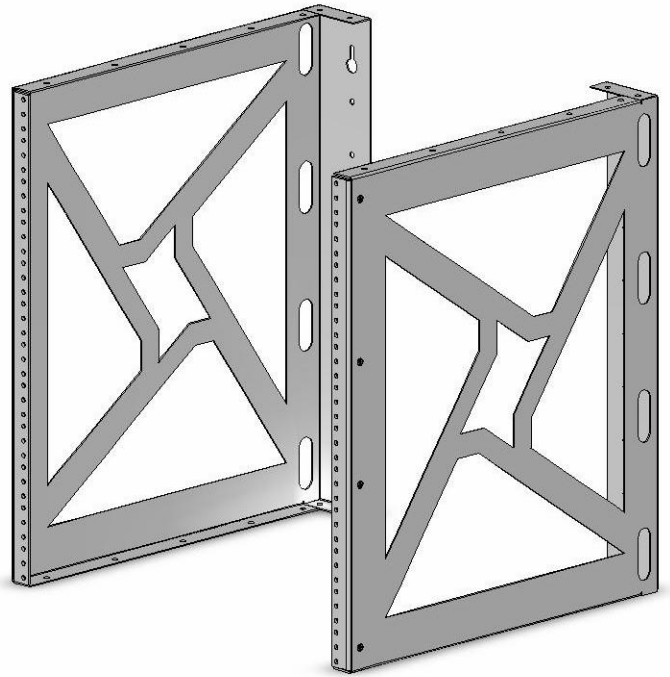

Step 2

Assemble each of wall base units by attaching the rails to the base units with the supplied screws.

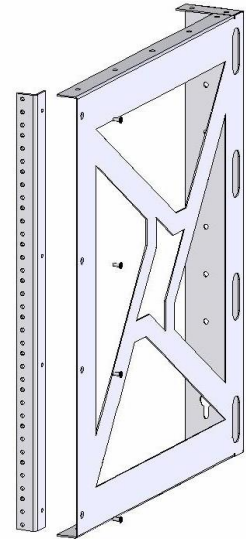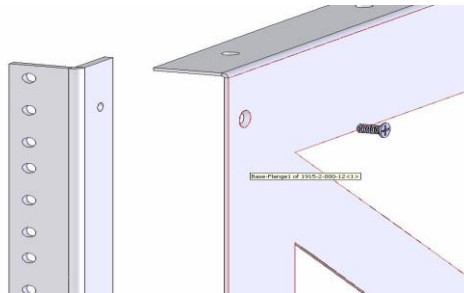

Step 3

With an electronic stud finder, locate the exact center of a wall stud where you would like to mount the rack. Mark the wall with a pencil where the top of the wall rack will be. Tape the stencil to the wall lining up your mark with the arrow on the template. Make sure that the template is level on the wall. We recommend using 2.5" common drywall screws driven directly into the center of a wood stud. Screw in the first screw leaving the head around 1/4" from the wall into template holes 1 and 2. Leaving the template in place, Hang both sides on the screws through the keyhole provided at the top of each base. Screw in screws 3 and 4 but do not fully tighten. Remove the template by pulling from the bottom. Add the additional screws and tighten the top and bottom screws.

NOTE: YOU MUST ATTACH THIS RACK TO A SOLID MATERIAL SUCH AS A WOODEN WALL STUD. DO NOT USE DRYWALL HANGERS OR WALL ANCHORS AS THESE DO NOT PROVIDE A STURDY MOUNTING METHOD. IF YOUR ENVIRONMENT HAS METAL OR CONCRETE, CONSULT YOUR LOCAL BUILDING MAINTENANCE ADMINISTRATION BEFORE MOUNTING. AS WITH ALL DEVICES PERMANENTLY MOUNTED TO WALLS AND BUILDING STRUCTURES, YOU SHOULD CONSULT A LICENSED CONTRACTOR BEFORE MAKING THE INSTALLATION.