


Series C

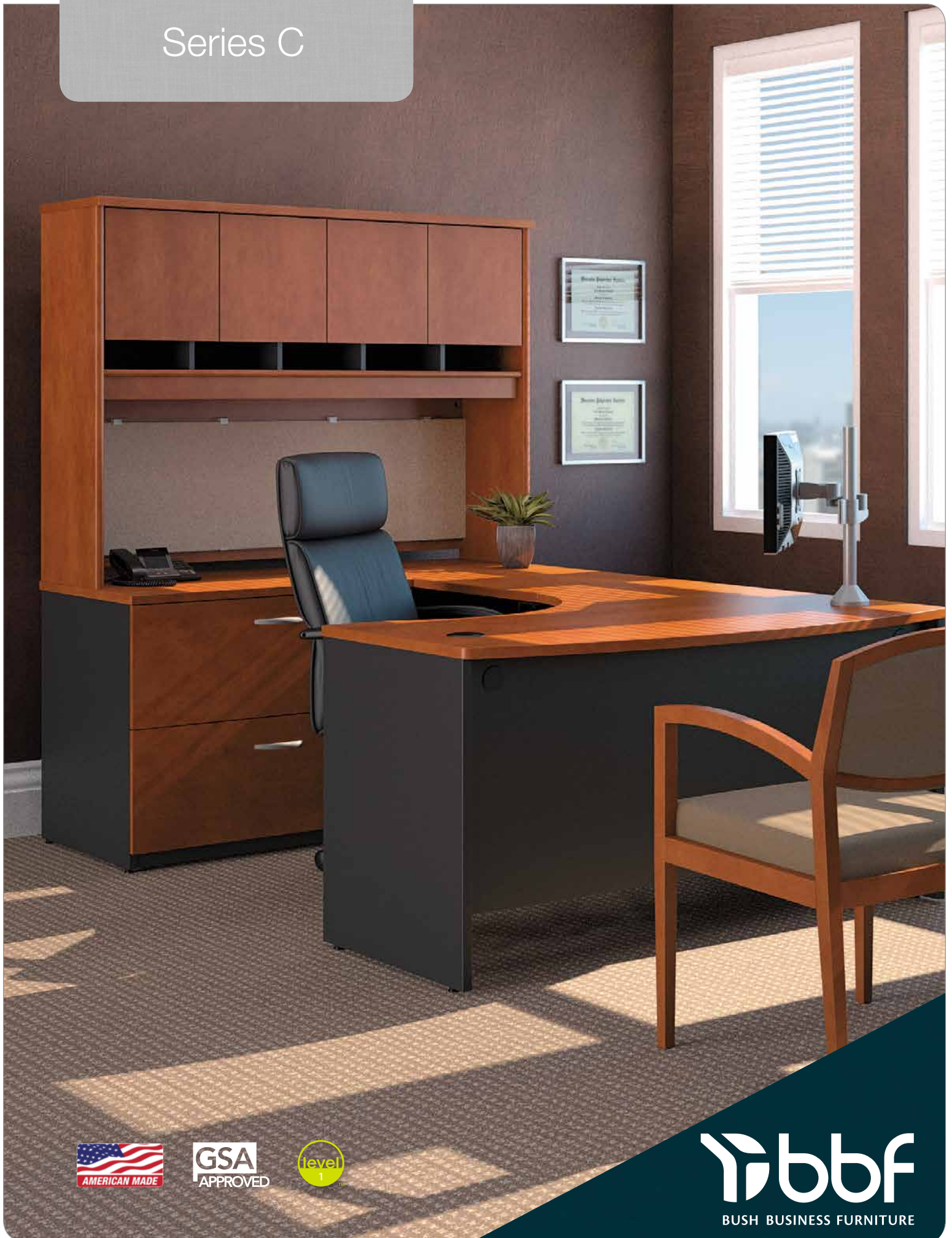

Series C





Classic styling with clean lines
and extended modesty panels.

Series C





Light Oak

Classic Shell desk design at a great value. Ideal for closed offices and wherever professionals work: reception areas, conference rooms and Work at Home Professionals.

- ☑ Durable, thermally fused laminate work surfaces feature superior resistance to scratches and stains
- ☑ Quick assembly with optional pre-assembled storage and filing components
- ☑ Durable edge banding on work surface resists collisions and dents
- ☑ Self-closing Euro-style hinges
- ☑ Full-extension ball bearing drawer slides on file drawers
- ☑ Integrated wire management
- ☑ Meets ANSI/BIFMA standards for safety and performance
- ☑ Commercial quality backed by 10-Year Warranty
- ☑ American made

Features





Open storage and tackboards
organize active projects



Durable Work Surfaces



Attractive and professional
closed leg design

Work Surfaces and Extensions

- ☑ Thermally fused laminate with durable edge band to resist scratches and dents
- ☑ All Work Surfaces and leg end panels are 1" thick
- ☑ Each end panel has levelers to adjust for uneven floor surfaces (½" adjustment range)
- ☑ All desk Work Surfaces feature wire management grommets which can accept Monitor Arm w/Post (sold separately)
- ☑ Dual-cavity wire channel mounts to Modesty Panels in two convenient locations; accommodates electrical cords and standard size power strips
- ☑ Snap down wire clips on channels hold wires in place
- ☑ Desk surfaces are 30" deep
- ☑ Credenza surfaces are 24" deep

Hutch Storage

- ☑ All Hutches include fully finished back panel and fabric covered tackboard
- ☑ Mounts conveniently to desk, Lateral Files or Storage Cabinets
- ☑ Overall height of Desk/Hutch unit is 72"

Storage

Storage Cabinet and Piler/Filer

- ☑ Grommet in back panel for wire access in Storage Cabinet
- ☑ Adjustable leveling glides
- ☑ Adjustable shelving Bookcase construction

Bookcase Construction

- ☑ Three adjustable shelves
- ☑ Two fixed shelves
- ☑ Optional door for Single Bookcase hinged on right or left side in lower position
- ☑ Bookcases match Hutch height and depth

Filing

File and Pedestal Construction

- ☑ Includes Brushed Nickel finish drawer pulls
- ☑ Drawer interiors finished in Black
- ☑ Case exterior finish matches desk end panels
- ☑ Includes face front lock with interchangeable core in lower drawer that secures both the lower and upper drawer
- ☑ All file drawers equipped to accommodate hanging folders

Lateral Files

- ☑ File drawers accommodate legal, letter and A4 file sizes
- ☑ Lateral File drawers glide on full-extension, ball bearing slides
- ☑ Interlocking drawer mechanism on Lateral File prevents both drawers from opening at the same time
- ☑ All pieces in collection ship keyed alike, additional cores available

Mobile Pedestal (F/F) and Mobile Pedestal (B/B/F)

- ☑ Dual-wheeled, hooded casters: two swivel, two fixed
- ☑ Face front lock with interchangeable core secures lower and center drawer in Mobile Pedestal (B/B/F)
- ☑ All file drawers extend on full-extension, ball bearing slides

Finishes





Mocha Cherry




Natural Cherry



Hansen Cherry

Finish Options


Use below finish codes where XXX is indicated in Sku #

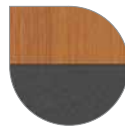

Natural Cherry/
Graphite Gray
(724)



Auburn Maple/
Graphite Gray
(485)

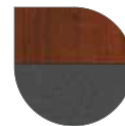

Hansen Cherry/
Graphite Gray
(244)



Light Oak
(603)



Warm Oak
(675)



 
Mahogany
(367)



Mocha Cherry
(129)

Statement of Line


Work Surfaces/Extensions




72"W x 36"D Bow
Front Desk Shell
WCXXX46



 
60"W x 43"D RH
L-Bow Desk Shell
WCXXX22




60"W x 43"D LH
L-Bow Desk Shell
WCXXX33

 


72"W x 30"D
Desk Shell
WCXXX36

 


66"W x 30"D
Desk Shell
WCXXX42A

 

72"W x 36"D
RH Corner Module
WCXXX23

 


72"W x 36"D
LH Corner Module
WCXXX32

 


48"W x 24"D
Return Bridge
WCXXX24



 36"W x 24"D
Return Bridge
WCXXX18



72"W x 24"D
Credenza Shell
WCXXX26

 


60"W x 24"D
Credenza Shell
WCXXX61




36"W x 22"D
Adjustable Height
Mobile Table
WCXXX82

 
Storage/Filing




72"W Hutch
(4-Door)
WCXXX77

 


72"W Hutch
(2-Door)
WCXXX66

 


60"W Hutch
(4-Door)
WCXXX62

 

30"W
Hutch
WCXXX97

 

24"W
Hutch
WCXXX06

 


Reception
L-Shelf
WCXXX76




24"W x 24"D
Piler/Filer
WCXXX04



 30"W x 24"D
Storage Cabinet
WCXXX96A



36"W x 16"D
5-Shelf Bookcase
WCXXX14

 

18"W x 16"D
5-Shelf Bookcase
WCXXX12



 
Half Height
Door Kit (2-Doors)
WCXXX11



36"W x 24"D
2-Drawer
Lateral File
(Assembled)
WCXXX54ASU



Mobile Pedestal
(B/B/F)
(Assembled)
WCXXX53SU



Mobile Pedestal
(F/F)
(Assembled)
WCXXX52SU

 


3/4 Pedestal
(B/F)
(Assembled)
WCXXX90SU


Conference Tables/Accessories



42"W Round
Conference Table
TBXXX42



 
82"W x 35"D
Racetrack
Conference Table
TRXXX84A



Articulating
Keyboard Tray
AC99801-03



 Deluxe Articulating
Keyboard Tray
(Long Track)
AC99889




Universal
Keyboard Shelf
AC99808-03



Task Light
WC8065C-03



 Multi-Purpose
Drawer
w/Drop Front
AC99855-03



Pencil
Drawer
AC99850



Data/Power
HUB
AC99840-03



Monitor Arm
w/Post
AC99830-03

Product Warranty

We understand the demands for safety and durability. That's why our materials and construction methods undergo rigorous testing to ensure all of our commercial products meet ANSI/BIFMA standards.

We test:

- Resistance to scratches, stains and abrasions
- Weight load
- Leg strength
- Stability/dislodgement
- Cycle testing on casters, hinges and drawer slides



The result of this attention to quality is a **Five-Year, Ten-Year or Limited Lifetime Warranty** on all BBF products. They are also ergonomically correct and compliant with state and federal health and safety guidelines.

Environmental Sustainability

At BBF, we are proud to be good stewards of the environment, taking care to be environmentally conscious from the beginning to the end of our manufacturing process.

Some of our environmental initiatives include:

- **BIFMA level®:** Bush Industries Inc. has received level® 1 certification for several product lines manufactured at our Jamestown, NY facility
- **CARB:** All BBF products are compliant with CARB (California Air Resource Board) standards for reduced formaldehyde emissions
- **EPP Downstream Program (Composite Panel Association):** More than 50% of panels purchased from EPP sources; board is 100% pre- or post-consumer recycled
- **Energy Reduction:** Reducing electricity consumption and improving machinery efficiency
- **Landfill Reduction:** Diversion of plastic waste away from landfills and improved recycling of plastic, cardboard, tin and scrap metal
- **Corporate Recycling:** Recycling plastic, paper and aluminum cans in our corporate offices
- **Special Sustainability Teams:** Tasked with improving efficiency and reducing waste in our manufacturing processes



How can we help you?

Please call us for assistance with questions regarding space planning, product availability, parts replacement, warranty issues and general product information.

Office hours are Monday-Friday, 8 am–5 pm ET excluding major holidays.

Sales Assistance	800-964-1638
Service Issues	800-950-4782



What you need.

Our **total turnkey solution** has everything you need for hassle-free furniture buying. With the right products and services, we ensure you get great furniture **fast, easily, and affordably.**

.....

Where you need it.

Across the street or across the country, we specialize in small orders and fast turnarounds to **remote locations at the same flat rate.**

.....

When you need it.

Ready to ship within 24 hours of order receipt, delivered to your dock in 5 business days, **installed nationwide within 10 business days***.

*remote locations may take longer



One Mason Drive
PO BOX 460
Jamestown, NY 14702-0460
800.964.1638
Fax: 716.665.2074
www.bbffits.mobi

To reorder this catalog e-mail
literature@bushindustries.com

BBFSRC416 4/16