

StreamLine® Low Profile Steady Burning LED Light

Model LP3SL, LP3PL, LP3TL, LP3ML



COMPACT, ECONOMICAL AND FLEXIBLE

- Available in 24VDC and 120VAC
- T-mount, integrated 1/2 - inch pipe mount, 1/2 - inch male pipe mount or surface mount
- Five dome/lens colors available
- 100,000 LED lamp life*
- Screw on lens
- Indoor/Outdoor use
- Type 4X enclosure
- Optional wire lens guard
- UL and cUL Listed, CSA Certified

Federal Signal introduces the Model LP3L low profile LED light. The Type 4X light is available in five LED/lens color combinations; amber, blue, clear, green and red. All LP3 models feature the easy access screw on lens.

The LP3L is offered in four mounting configurations; LP3PL with an integrated 1/2-inch NPT pipe mount, LP3ML features an integrated 1/2-inch male pipe mount, LP3TL features a T formation base with 2 mounting holes for wall or flush mounting and the LP2SL features a three hole surface mounting configuration. The T-mount and Surface mount units include surface gaskets to maintain the 4X installation.

The LP3L series is available in 24VDC and 120VAC. All models include the vibration resistant, double contact bayonet style 100,000 hour LED module.

Like all StreamLine® products, the LP3L is designed with OEM applications in mind. It is economical, easy to install and attractive. Careful consideration has been given to the relationship between the LED light source and the lens design for maximum light output.


When your application calls for a compact signal with unparalleled reliability, Federal Signal's StreamLine products are the clear choice.

Model	Voltage	Operating Current
LP3L	24VDC	0.08 amps
LP3L	120VAC	0.13 amps

* Optimal hours under ideal conditions.



STREAMLINE® LOW PROFILE STEADY BURNING LED LIGHT (LP3SL/LP3PL/LP3TL/LP3ML)

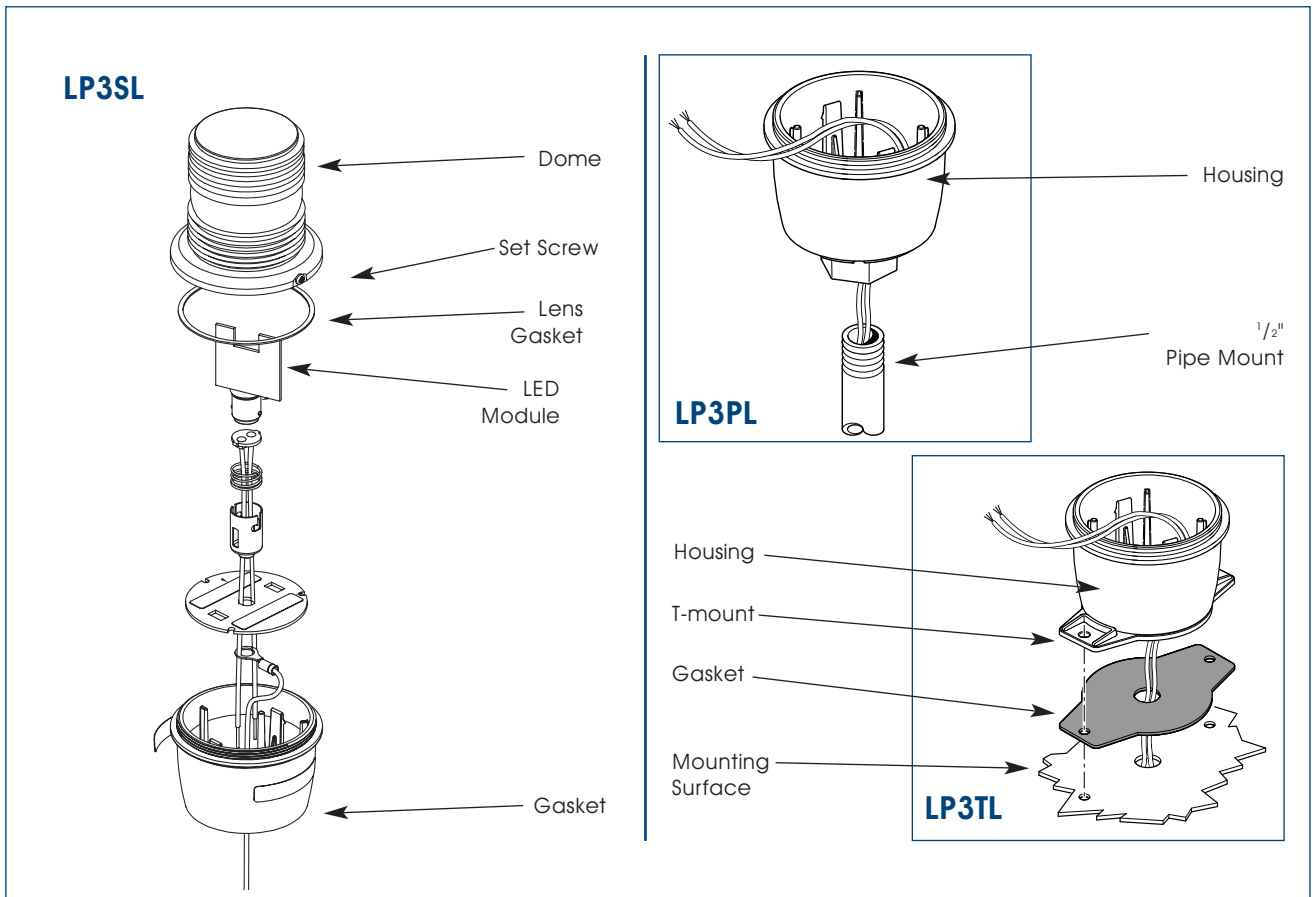

SPECIFICATIONS

Lamp Life*:	100,000 hours	100,000 hours
Operating Temperature:	-31°F to 150°F	-35°C to 65°C
Net Weight:	0.46 lbs.	206.96 g
Shipping Weight:	0.53 lbs.	240.98 g
Diameter:	3.13"	7.95 cm
Height (from bottom):		
LP3PL	5.7"	14.48 cm
LP3ML	5.8"	14.7 cm
LP3TL	5.1"	12.95 cm
LP3SL	5.0"	12.7 cm

* Optimal hours under ideal conditions.

REPLACEMENT PARTS

Description	Part Number	Description	Part Number
Lens, Amber	K8589063A	LED, 24V Amber	K8107199A
Lens Blue	K8589063A-01	LED, 24V Blue	K8107199A-03
Lens, Clear	K8589063A-02	LED, 24V Clear	K8107199A-04
Lens, Green	K8589063A-03	LED, 24V Green	K8107199A-02
Lens, Red	K8589063A-04	LED, 24V Red	K8107199A-01
Gasket, LP3TL	K8589012A	LED, 120V Amber	K8107200A
Gasket, LP3SL	K8589011A	LED, 120V Blue	K8107200A-03
Gasket, Lens	K8589013A	LED, 120V Clear	K8107200A-04
		LED, 120V Green	K8107200A-02
		LED, 120V Red	K8107200A-01

HOW TO ORDER

- Specify model, voltage and color
- Specify options (wire guard - LP3G)
- Please refer to Model Number Index LP3L beginning on page 374